


Laminated Plywood with Edge Moldings

Soft Edge / Adhesive

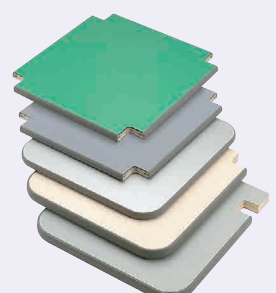

<Laminated Plywood with Soft Edge Moldings>
PBDAR (Laminated Plywood)
MPB□□□□**R** (Melamine Resin + Laminated Plywood)
NTB□□□□**R** (Rubber + Laminated Plywood)
ATB□□□□**R** (Antistatic Rubber + Laminated Plywood)
ALB□□□□**R** (Aluminum + Laminated Plywood)

<End Tape Glued Laminated Plywood>
MPB□□□□**T** (Melamine Resin + Laminated Plywood)

Soft Edge
 Thickness of Surface Material Refer to the table on the right.
MPB□□□□**R**
NTB□□□□**R**
ATB□□□□**R**
ALB□□□□**R**


Soft Edge
 Material Polypropylene + Elastomer
 Allowable Temperature ~80°C
 Color Gray
Tape
 Material Acrylic-impregnated paper (Thickness 0.45mm)
 Color Beige

Table:

Type	Glued	Thickness of Surface Material (mm)	Material
PBDAR	None	-	Laminated Plywood (Poplar)
MPB□□□□	Both Sides	0.5	Melamine Resin Laminated Plywood
NTB□□□□	Single Side	2	Rubber Coated Plywood
ATB□□□□	Single Side	2	Antistatic Rubber Coated Plywood
ALB□□□□	Both Sides	0.8	Aluminum Glued Laminated Plywood

Dimensions:
 B±0.5, A±0.5, T±0.5, T±0.5
 T Dimension 10, 12=t3 T Dimension 14, 15, 16=t4 T Dimension 20=t5

Notches:
 The shape of the notches are as shown below.

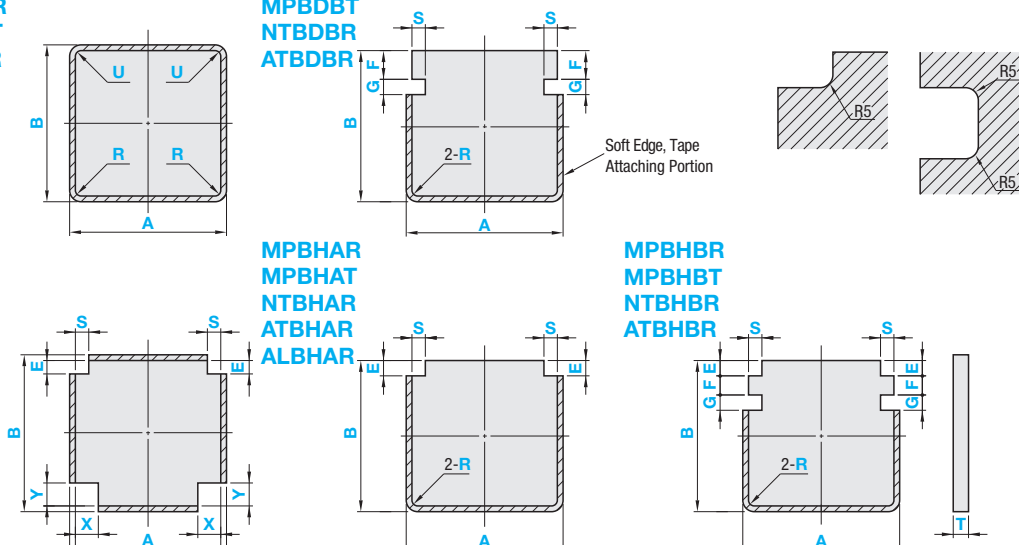


Part Number Selections:
PBDAR
MPBDAR
MPBDAT
NTBDAR
ATBDAR
ALBDAR
MPBDBR
MPBDBT
NTBDBR
ATBDBR
MPBHBR
MPBHBT
NTBHBR
ATBHBR
ALBHBR

Part Number	A Selection	B Selection	Color	R U Selection	E G S X Y F
PBDAR	12 16 20		-		
MPBDAR	10 15 20		S (Gray)	10	
MPBDAT	10 15 20		G (Light Gray)	10	
NTBDAR	10 14 20		L (Light Green)	20	
ATBDAR	10 14 20		-		
ALBDAR	10 15 20		-		
MPBDBR	10 15 20		S (Gray)	30	
MPBDBT	10 15 20		G (Light Gray)	30	
NTBDBR	10 14 20		L (Light Green)	30	F
ATBDBR	10 14 20		-		
MPBHR	10 15 20	200~1200	S (Gray)		
MPBHT	10 15 20	200~1200	G (Light Gray)		
NTBHR	10 14 20	200~1200	L (Light Green)		
ATBHR	10 14 20	200~1200	-		
ALBHR	10 15 20	200~1200	-		
MPBHAR	10 15 20	200~1000	S (Gray)		
MPBHAT	10 15 20	200~1000	G (Light Gray)		
NTBHAR	10 14 20	200~1000	L (Light Green)		
ATBHAR	10 14 20	200~1000	-		
ALBHAR	10 15 20	200~1000	-		
MPBHBR	10 15 20	200~1000	S (Gray)		
MPBHBT	10 15 20	200~1000	G (Light Gray)		
NTBHBR	10 14 20	200~1000	L (Light Green)		F
ATBHBR	10 14 20	200~1000	-		

Actual Dimension T

Nominal Dimension	10	15	20
Aluminum Glued Laminated Plywood	9.6	13.6	19.6

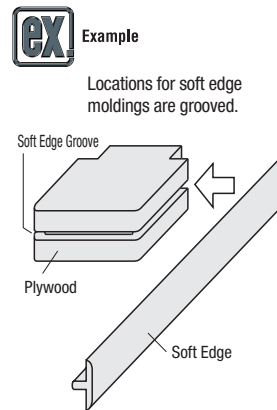


Ordering Example

Part Number - A - B - Color - R - U - E, G, S, X, Y, F
 Example: MPBHR20 - 800 - 600 - S - R - U - E30-S30-X30-Y30
 MPBDAT10 - 320 - 250 - S - R10 - U10

Base Plate Price

Part Number	A Selection	Unit Price				Part Number	A Selection	Unit Price			
		200-400	401-600	601-800	801-1000			200-400	401-600	601-800	801-1000
<Laminated Plywood> PBDAR (Soft Edge)	12	200~ 400				<Rubber Coated Plywood> NTBDAR NTBDBR NTBHR NTBHBR (Soft Edge)	14	200~ 400			
		401~ 600						401~ 600			
		601~ 800						601~ 800			
		801~1000						801~1000			
		1001~1200						1001~1200			
		1001~1200						1001~1200			
	16	200~ 400				<Antistatic Rubber Coated Plywood> ATBDAR ATBDBR ATBHR ATBHBR (Soft Edge)	20	200~ 400			
		401~ 600						401~ 600			
		601~ 800						601~ 800			
		801~1000						801~1000			
		1001~1200						1001~1200			
		1001~1200						1001~1200			
<Melamine Resin Glued Laminated Plywood> MPBDAR MPBDBR MPBHR MPBHAR MPBHBR (Soft Edge)	10	200~ 400				<Aluminum Glued Laminated Plywood> ALBDAR ALBHR ALBHAR ALBHBR (Soft Edge)	15	200~ 400			
		401~ 600						401~ 600			
		601~ 800						601~ 800			
		801~1000						801~1000			
		1001~1200						1001~1200			
		1001~1200						1001~1200			
	15	200~ 400				<End Tape Glued Laminated Plywood> MPBDAT MPBDBT MPBHT MPBHAT MPBHBT (End Tape Glued) Material Multiplier (x0.9)	20	200~ 400			
		401~ 600						401~ 600			
		601~ 800						601~ 800			
		801~1000						801~1000			
		1001~1200						1001~1200			
		1001~1200						1001~1200			
20	200~ 400				<Notching Charge> Applicable Codes (Notching) E G Y (Corner R) U R	10	200~ 400				
	401~ 600						401~ 600				
	601~ 800						601~ 800				
	801~1000						801~1000				
	1001~1200						1001~1200				
	1001~1200						1001~1200				
20	200~ 400				(Ex.) Part Number - A - B - Color - R - U - E:S MPBHAR10 - 800 - 600 - S - R20 - E30-S30	15	200~ 400				
	401~ 600						401~ 600				
	601~ 800						601~ 800				
	801~1000						801~1000				
	1001~1200						1001~1200				
	1001~1200						1001~1200				
20	200~ 400				The price of End Tape Glued Laminated Plywood is found by multiplying the Unit Price by Material Multiplier 0.9. (Ex.) Part Number - A - B - Color - R - U - E:S MPBDAT10 - 320 - 250 - S - R10 - U10 (Unit Price) x (Material Multiplier) + (Notching Charge) = Price of End Tape Glued Laminated Plywood	20	200~ 400				
	401~ 600						401~ 600				
	601~ 800						601~ 800				
	801~1000						801~1000				
	1001~1200						1001~1200				
	1001~1200						1001~1200				

End Tape Glued Laminated Plywood

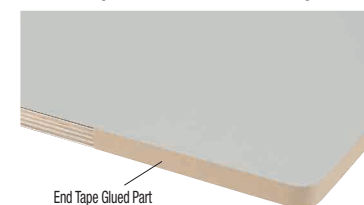

End tape glued products to prevent wood tips from scattering.