


# SPACERS FOR TAPERED PIN SET



PRINTED IN RED

The quantity discount rate is also applicable to alteration cost.  
All price & lead time are to be quoted.

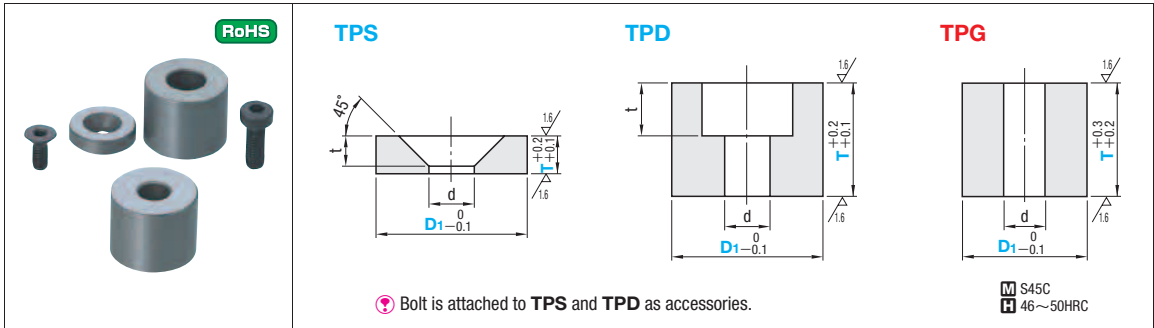

☛ Bolt is attached to TPS and TPD as accessories.

Applicable tapered pin D	Plate thickness	d	t	Supplied bolts	Part Number		U/Price 1~9 pcs.
					Type	D1	
13	20	4.5	3.0	FB 4-10 FB 4-15	TPS	16	5
	25					10	
16	20	5.5	3.0	FB 5-12 FB 5-16	TPS	20	5
	25					10	
20	25	6.5	4.0	FB 6-12 FB 6-16	TPS	25	5
	30					10	
25	30	8.5	4.5	FB 8-15 FB 8-20	TPS	32	5
	35					10	
30	40	10.5	7.5	FB 10-20 FB 10-20	TPS	35	10
	32					10	
10	25	4.5	6	CB 4-10 CB 4-15 CB 4-20	TPD	13	10
	30						15
	35						20
	40						25
13	25	4.5	6	CB 4-25 CB 4-10 CB 4-15	TPD	16	10
	30						15
	35						20
	40						25
16	25	5.5	7	CB 5-10 CB 5-15 CB 5-20	TPD	20	10
	30						15
	35						20
	40						25
20	25	6.5	9	CB 5-25 CB 5-30 CB 5-35	TPD	25	10
	30						15
	35						20
	40						25
25	30	8.5	10	CBS 6-16 CB 6-15 CB 6-20	TPD	32	10
	35						15
	40						20
	45						25
30	40	10.5	12	CB 6-25 CB 6-30 CB 6-40	TPD	35	10
	45						15
	50						20
	60						25
32	50	12.5	14	CB 6-50 CB 8-15 CB 8-20	TPD	38	10
	60						15
	70						20
	80						25
35	50	12.5	14	CB 8-25 CB 8-35 CB 8-45	TPD	42	10
	60						15
	70						20
	80						25
42	50	12.5	14	CB 8-55 CB 10-20 CB 10-30	TPD	48	10
	60						15
	70						20
	80						25

Applicable tapered pin D	Plate thickness	d	Applicable bolts M	Part Number		U/Price 1~9 pcs.
				Type	D1	
8	20	3.5	M 3	TPG	8	5
	25				10	
10	20	4.5	M 4	TPG	10	5
	25				10	
13	20	4.5	M 4	TPG	13	5
	25				10	
16	20	5.5	M 5	TPG	16	5
	25					10
	30					15
	35					20
20	25	6.5	M 6	TPG	20	5
	30					10
	35					15
	40					20
25	30	8.5	M 8	TPG	25	5
	35					10
	40					15
	45					20
30	35	10.5	M10	TPG	30	5
	40					10
	45					15
	50					20
32	40	10.5	M10	TPG	32	5
	45					10
	50					20
	60					30
35	40	12.5	M12	TPG	35	5
	45					10
	50					15
	60					25
42	45	12.5	M12	TPG	42	5
	50					10

Quotation

Quotation

☛ Sizes marked\* are discontinued at April 2010.

☛ Sizes marked\* are discontinued at April 2010.



Order

Part Number — T  
TPS20 — 10



Delivery

Printed in Red • Printed in Blue  
SGP Stock 3 Days

☛ For area out of Singapore, please refer to Pi.

### Quantity discount rate

Quantity	1~9	10~29	30~99	100~200
Rate	—	5%	10%	15%

☛ To be quoted on price & lead time above Max. Q'ty.