


## Information on Components Used


### Connector / Hood

AR / EAR / BHAR / GRNA / GRNAE / GRNAH

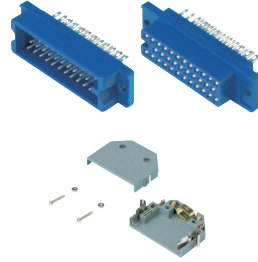

Connector	
Manufacturer	Honda Tsushin Kogyo Co., LTD.
Model Number	MR-**
Rated Current	3A or less
Rated Voltage	300 VAC or less
More Information	OP.93
Straight Hood	
Manufacturer	Honda Tsushin Kogyo Co., LTD.
Model Number	MR-*L+
More Information	OP.94
Hood for Relay	
Manufacturer	Honda Tsushin Kogyo Co., LTD.
Model Number	MR-*LK2+
More Information	OP.94

### Crimp Terminal

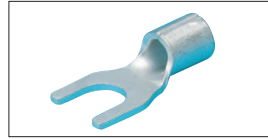


Y Type Crimp Terminals	
Manufacturer	Daido Solderless Terminal Mfg. Co.
Model Number	F0.3-3 F0.08-3 Equivalent
Size	3.2mm
Outer Width	5.2mm
Model Number	F1.25-3.5 Equivalent
Size	3.5mm
Outer Width	6.0mm
More Information	OP.468



Round Type Crimp Terminals	
Manufacturer	Daido Solderless Terminal Mfg. Co.
Model Number	0.3-3 Equivalent
Size	3.2mm
Outer Width	5.2mm
More Information	OP.464

### Ground Wire / Ground Terminal

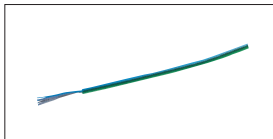


Single-Core Wire for Ground (Common for All Model Numbers)	
Model Number	UL1007-16-GN Equivalent
Standard Acquired	UL1007
Bending Radius	Finished Outer Diameter x 8



Crimp Terminal for Ground	
Model Number	RBA1.25-3.5RE Equivalent
Size	3.7mm
Outer Width	6.6mm
Rated Voltage	300V
More Information	OP.472

### Single-core Wire

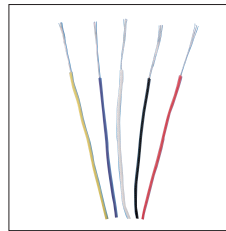

A, B, C, D, E, BA, BB Cables	
Manufacturer	—
Model Number	UL1007 Equivalent
Standard Acquired	AWM1007
Rated Temperature	0°C ~ 80°C
Flame Retardance	—
Bending Radius mm (Fixed Parts)	—
Bending Radius mm (Movable Parts)	—
More Information (Reference)	OP.1375 (Similar Specifications)

Connector Included Cable Selection Method

Square Connector Included Cable

Coaxial Connector Included Cable

Round Connector Included Cable


Nylon Connector Included Cable

Custom Service

Connector Included Cable Documents

### Multi-Core Cable

AR / EAR SB Cable

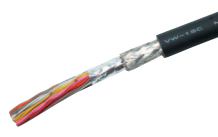

Manufacturer		Misumi
Model Number		SS30WS
Standard Acquired		AWM20276
Rated Temperature		80°C
Flame Retardance		VW-1SC
Bending Radius mm (Fixed Parts)		Finished Outer Diameter x 8
Bending Radius mm (Movable Parts)		—
More Information		OP.1339

AR / EAS E Cable



\* 50-core is NA28WSH  
OP.1338

Manufacturer		Misumi
Model Number		NA28WSB
Standard Acquired		AWM2464
Rated Temperature		-10°C ~ 80°C
Flame Retardance		—
Bending Radius mm (Fixed Parts)		Finished Outer Diameter x 8
Bending Radius mm (Movable Parts)		—
More Information		OP.1298

AR / EAR JS Cable



Manufacturer		Misumi
Model Number		SS300SB
Standard Acquired		AWM2464
Rated Temperature		0 ~ 80°C
Flame Retardance		VW-1
Bending Radius mm (Fixed Parts)		Finished Outer Diameter x 6
Bending Radius mm (Movable Parts)		—
More Information		OP.1291

AR / EAR MS Cable




Manufacturer		Misumi
Model Number		SS300RSB
Standard Acquired		AWM2464
Rated Temperature		0 ~ 80°C
Flame Retardance		VW-1
Bending Radius mm (Fixed Parts)		Finished Outer Diameter x 6
Bending Radius mm (Movable Parts)		Finished Outer Diameter x 6
More Information		OP.1505

GRNA / GRNAE WA Cable



Manufacturer		Misumi
Model Number		MAST-UL20276SB-28
Standard Acquired		ULAWM20276
Rated Temperature		0 ~ 80°C
Flame Retardance		VW-1
Bending Radius mm (Fixed Parts)		Finished Outer Diameter x 10
Bending Radius mm (Movable Parts)		—
More Information		OP.1333

GRNA / GRNAE WB Cable

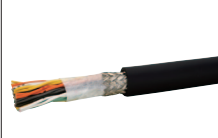

Manufacturer		Misumi
Model Number		MAST-UL2464SB-28
Standard Acquired		ULAWM2464
Rated Temperature		0 ~ 80°C
Flame Retardance		VW-1
Bending Radius mm (Fixed Parts)		Finished Outer Diameter x 6
Bending Radius mm (Movable Parts)		—
More Information		OP.1285