

Caster Dual Wheel Type

Medium Load / Ultra Heavy Load

Caster Dual Wheel Type

Heavy Load Steel / Stainless Steel

Medium Load **CWM-P**

Main Body		Wheel	Bearing
M	S	M	Swiveling Part
Material	Surface Treatment	Material (Color)	Wheel
SPHC	Trivalent Chromate	Nylon (Black)	Incorporated
			None

RoHS 10

Main Body	Part Number		Wheel Material	H	d	r	Allowable Load (N)	Mass (g)	Unit Price
	Type	D							
Swivel	CWM-P	38	N (Nylon)	64	8.8	44	1200	450	
		50		77					

Ordering Example: Part Number - Wheel Material
CWM-P38 - N

Features: Has the max. allowable load in our lineup. Can be used for traction of large processing machines and dedicated devices by motor power.


Ultra Heavy Load **CKXJ**

Main Body		Wheel	Bearing
M	S	M	Swiveling Part
Material	Surface Treatment	Material (Color)	Wheel
SPHC	Trivalent Chromate	MC Nylon (Blue)	Incorporated
			Incorporated

RoHS 10

Main Body	Part Number		Wheel Material	H	r	Allowable Load (N)	Mass (g)	Unit Price
	Type	D						
Swivel	CKXJ	100	M (MC Nylon)	150	97	10000	5300	
		125		170	109	13000	5700	
		150		200	121	15000	6300	

Ordering Example: Part Number - Wheel Material
CKXJ100 - M

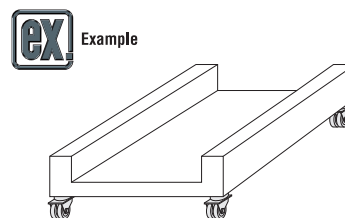

Heavy Load - Steel - **CWMJ**

Main Body		Wheel	Bearing
M	S	M	Swiveling Part
Material	Surface Treatment	Material (Color)	Wheel
SPHC	Trivalent Chromate	MC Nylon (Blue)	Incorporated
			Incorporated

RoHS 10

EX Example

Turning direction
Wheel Rotation Direction

• Dual wheel casters exhibit better load capacity and swiveling than single wheel.

Main Body	Part Number		Wheel Material	H	D1	B	A	F	d	t	E	r	Allowable Load (N)	Mass (g)	Unit Price
	Type	No.													
Swivel	CWMJ	50	N (MC Nylon)	75	42	38	84	64	8.5	3.2	12	49	4000	812	
		65		93	57	48	100	78	10.5	4.5	14	57	5000	1530	
		75		102	65										6000

Heavy Load - Stainless Steel - **CWG**

Main Body		Wheel	Seal	Bearing
M	S	M	Material	Swiveling Part
Material	Surface Treatment	Material (Color)	Material	Wheel
SUS304	-	Monomer Casting Nylon (Blue) Electrically Conductive MC Nylon (Black)	Polyacetal	Incorporated
				Incorporated

RoHS 10

Dust-proof Seal

Main Body	Part Number		Wheel Material	H	A	F	d	E	r	Allowable Load (N)	Mass (g)	Unit Price	
	Type	D										Monomer Casting Nylon	Electrically Conductive MC Nylon
Swivel	CWG	50	N (Monomer Casting Nylon) D (Electrically Conductive MC Nylon)	75	84	64	8.5	12	43	4000	760		
		65		93	100	78	10.5	15	54	5000	1060		
		75		102						58	6000	1120	

Ordering Example: Part Number - Wheel Material
CWMJ50 - N
CWG50 - D