



DOUBLE ACTING ROUND/SQUARE AIR NIPPERS / BLADES FOR DOUBLE ACTING AIR NIPPER

Double Acting Air Nipper

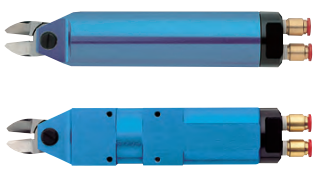

MGT-NWR (Round Type)
MGT-NWS (Square Type)

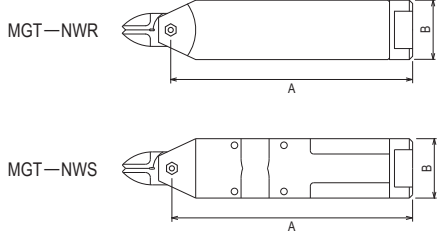

The hose fitting is sold separately

Double Action Air Scissors (Round Type without Lever)

Cutting capacity ϕ (mm)			Air consumption (cm ³ /str.)	Air Pressure (MPa)	Weight (g)	Part dimensions (mm)		Hose fitting	Part Number	Unit Price 1~9 pcs
Copper	Steel	ABS plastic				A	B			
1.8	1.2	4	116	0.4~0.5	280	146	ϕ 36	PT 1/8	MGT-NWR10	
2.6	2	6.5	230	0.5~0.6	523	165	ϕ 45	PT 1/8	MGT-NWR20	Quotation
3.3	2.8	9.5	584	0.5~0.6	980	230.5	ϕ 56	PT 1/4	MGT-NWR30	

Double Action Air Scissors (Square Type)

Cutting capacity ϕ (mm)			Air consumption (cm ³ /str.)	Air Pressure (MPa)	Weight (g)	Part dimensions (mm)		Hose fitting	Part Number	Unit Price 1~9 pcs
Copper	Steel	ABS plastic				A	B			
1	0.5	2	45	0.4~0.5	116	95	23×20	M8×0.8	MGT-NWS1	
1.8	1.2	4	116	0.4~0.5	356	146	36×36	PT 1/8	MGT-NWS10	
2.6	2	6.5	230	0.5~0.6	610	165	45×45	PT 1/8	MGT-NWS20	Quotation
3.3	2.8	9.5	584	0.5~0.6	1115	230.5	56×56	PT 1/4	MGT-NWS30	

For quantities not displayed here, refer to our MISUMI website for more information.



Order

Part Number
MGT-NWR10
MGT-NWS1



Days to Ship

Quotation




Price

Quotation

Blades for Double Acting Air Nipper

MNW□□AJ

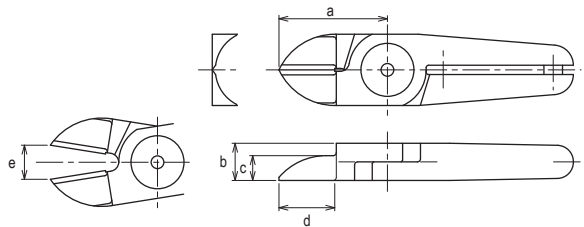

Applicable models	Cutting capacity ϕ (mm)				a	b	c	d	e	Weight (g)	Part Number			Unit Price 1~9 pcs
	Soft resin	Hard resin	Copper wire	Iron wire							Body No.	Cutting edge	Shape	
MGT-NWR10 / MGT-NWS10	-	4	-	-	30	9	6	14	5	76	MNW10	A	J	
MGT-NWR20 / MGT-NWS20	-	6.5	-	-	40	12	6	21.5	8	142	MNW20	A	J	Quotation
MGT-NWR30 / MGT-NWS30	-	9.5	-	-	55	17	8	29.5	11	368	MNW30	A	J	

For quantities not displayed here, refer to our MISUMI website for more information.



Order

Part Number
MNW10AJ



Days to Ship

Quotation



Price

Quotation