

# COMPONENTS FOR LIFTING AND DIE STORING

## COMPONENTS FOR LIFTING AND DIE STORING

Product name Catalog No.	LIFTING BARS HLFB	LIFTING EYE BOLTS CHI	CAST-IN LIFTING BOLTS CSN	HOOKS —BOLT TYPE— CHN
Page	1522	1523	1523	1524


HOOKS —LARGE HEAD BOLT TYPE— CHNL	HOOKS —LARGE HEAD PLATE TYPE— CHPL	HOOKS —PLATE TYPE— CHP	HOOKS —LARGE HEAD PLATE TYPE— CHPL	LIFTING HOOKS, INSERT TYPE CHU
1524	1528	1527	1528	1529

CAST-IN HOOKS CHF	CAST-IN HOOKS —LARGE HEAD TYPE— CHF L	T-SHAPED BOLTS TB	POWER POINT STARS — RDPPS	COBRA HOOK SET — RDPPS	STAR POINT RDSP
1530	1530	1530	1531	1531	1533

ROAD RINGS RDLG	VARIO RINGS RDBL	DIE FIXING PLATES DKP DKPL	HOLDING PIPES FOR TRANSPORT DYP	DIE STORAGE BUSHINGS KPB
1535	1537	1539	1539	1540

URETHANE STOCK BLOCK SETS PHBT PHBN PHUB PHUN	STROKE END PIPES PH PHN	URETHANE STOCK BLOCKS EST ESBT ESU ESUB	URETHANE ABSORBERS DUSA	URETHANE PADS DURP
1541 1542	1543	1544	1544	1544

# LIFTING BARS

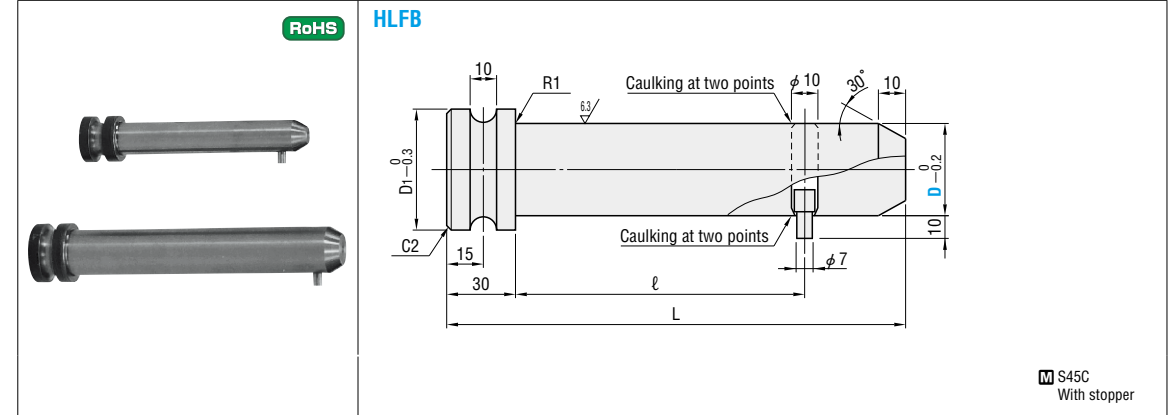

D1	L	l	Max. allowable load when 4 bars are used N (kgf)	Catalog No.		Base unit price 1 ~ 9 pieces
				Type	D	
34	185	135	29420 { 3000}	HLFB	25	Quotation
44	240	190	49033 { 5000}		35	
50	260	210	88260 { 9000}		40	
60	290	240	137293 {14000}		50	
75	335	285	166712 {17000}		65	

•Load (kgf)=Load N×0.101972



Catalog No.  
HLFB 25



Price  
Quotation



Days to Ship  
Quotation



Example Be sure to install with the locking stopper facing downwards.  
Install so that the flange does not protrude from the die during use.

